


Cut Grooving Tools for HDPE Pipe

CG3300/3500

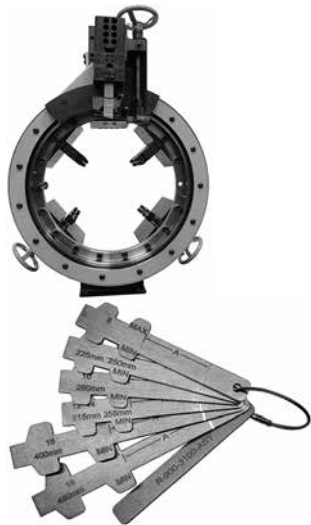

Cut grooving tools are designed for grooving 16 – 36" HDPE (DR7 – DR21) pipe. The tool mounts on the exterior pipe wall and cuts and grooves the end of the pipe in a single operation.

The CG3300 and CG3500 tools connect directly to a 120-volt, 50-60 Hz, 20-amp power source. An optional 220-volt single phase, 50-60 Hz model is also *regionally available.

Tool Model	Part Number	Tool Weight lb	Rental Per Month	Tool List Price
CG3300 – 16 – 26"/400 – 630 mm	R0003300CG	580	\$1655.00	\$99837.50
CG3500 – 24 – 36"/630 – 900 mm	R0003500CG	715	1655.00	133533.00

For tool rating capacity please reference publication 24.06.

REPLACEMENT TOOL BLADES/KNIVES

Tool Model	Size inches	Description	Part Number	Price Each
CG3300	16 – 22	Cutoff Stepped Blade	R111310022	\$724.50
CG3300/CG3500 - 24-36 Blade	24 – 36	Cutoff Stepped Blade	R111310036	749.00
CG3300/CG3500	16 – 36	Grooving Knife	R151310MCH	862.00

ACCESSORIES

Groove Confirmation Gauge	Part Number	Price Each
CG3300	R900330ASY	\$762.00
CG3500	R900350ASY	849.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

TERMS AND CONDITIONS OF SALE

Victaulic published Terms and Conditions of Sale listed in General Price List will apply. Prices, Designs and Conditions of Sale are subject to change without notice.

P.O. Box 31, Easton, PA 18044-0031 • 4901 Kesslersville Road, Easton, PA 18040 • 1-800-PICK-VIC (1-800-742-5842) • 1-610-250-8817 (fax) • pickvic@victaulic.com