

Price List Addendum

EFFECTIVE May 1, 2020

FireLock™
Installation-Ready™
Models V2721 and V2723

STANDARD RESPONSE
RACK STORAGE –
STANDARD ORIFICE
INTERMEDIATE LEVEL

Upright and Pendent
½" IGS Groove™ (15 mm)
½" (13 mm) Orifice
K5.6 (8.1 SI)

Refer to publication 40.22.



Upright V2721
with Style V9 Sprinkler
Coupling



Pendent V2723
with Style V9 Sprinkler
Coupling



Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S27JQCS41G	S27JRCS41G	\$45.50	\$45.50
200	93	S27JQFS41G	S27JRFS41G	45.50	45.50
286	141	S27JQJS41G	S27JRJS41G	45.50	45.50

FireLock™
Installation-Ready™
Models V3417 and V3419

STANDARD RESPONSE
RACK STORAGE –
LARGE ORIFICE
INTERMEDIATE LEVEL

Upright and Pendent
¾" IGS™ Groove (20 mm)
1⅞" (134mm) Orifice
K8.0 (11.5 SI)

Refer to publication 40.23.



Upright V3417
with Style V9 Sprinkler
Coupling



Pendent V3419
with Style V9
Sprinkler Coupling



Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S34KQCS51G	S34KRCS51G	\$50.50	\$50.50
200	93	S34KQFS51G	S34KRFS51G	50.50	50.50
286	141	S34KQJS51G	S34KRJS51G	50.50	50.50

FireLock™ Installation-Ready™ Sprinklers

FireLock™ Installation-Ready™ Models V2722 and V2724

**QUICK RESPONSE
RACK STORAGE –
STANDARD ORIFICE
INTERMEDIATE LEVEL**

Upright and Pendent
½" IGS™ Groove (15 mm)
½" (13 mm) Orifice
K5.6 (8.1 SI)
Refer to publication 40.22.



Upright V2722
with Style V9 Sprinkler
Coupling

Pendent V2724
with Style V9 Sprinkler
Coupling



Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S27JQCQ41G	S27JRCQ41G	\$49.50	\$49.50
200	93	S27JQFQ41G	S27JRFQ41G	49.50	49.50
286	141	S27JQJQ41G	S27JRJQ41G	49.50	49.50

FireLock™ Installation-Ready™ Models V3418 and V3420

**QUICK RESPONSE
RACK STORAGE –
LARGE ORIFICE
INTERMEDIATE LEVEL**

Upright, Pendent and Recessed Pendent
¾" IGS™ Groove (20 mm)
17/32" (14 mm) Orifice
K8.0 (11.5 SI)
Refer to publication 40.23.



Upright V3418
with Style V9 Sprinkler
Coupling

Pendent V3420
with Style V9
Sprinkler Coupling



Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S34KQCQ51G	S34KRCQ51G	\$61.50	\$61.50
200	93	S34KQFQ51G	S34KRQF51G	61.50	61.50
286	141	S34KQJQ51G	S34KRJQ51G	61.50	61.50

FireLock™ Installation-Ready™ Sprinklers

FireLock™ Installation-Ready™ Models V2703 and V2707

**STANDARD RESPONSE
COMMERCIAL – STANDARD ORIFICE**

Upright and Pendent
½" IGS™ Groove (15 mm)
½" (13 mm) Orifice
K5.6 (8.1 SI)

Refer to publication 40.10.



Upright V2703
with Style V9
Sprinkler Coupling



Pendent V2707
with Style V9
Sprinkler Coupling



Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S27JACS410	S27JBCS410	\$51.00	\$51.00
200	93	S27JAFS410	S27JBFS410	51.00	51.00
286	141	S27Jajs410	S27JBJS410	51.00	51.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Models V2704 and V2708

**QUICK RESPONSE
COMMERCIAL – STANDARD ORIFICE**

Upright and Pendent
½" IGS™ Groove (15 mm)
½" (13 mm) Orifice
K5.6 (8.1 SI)

Refer to publication 40.10.



Upright V2704
with Style V9
Sprinkler Coupling



Pendent V2708
with Style V9
Sprinkler Coupling




Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S27JACQ410	S27JBCQ410	\$55.00	\$55.00
200	93	S27JAFQ410	S27JBQ410	55.00	55.00
286	141	S27JAQ410	S27JBQ410	55.00	55.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Sprinklers

FireLock™ Installation-Ready™ Model V2709

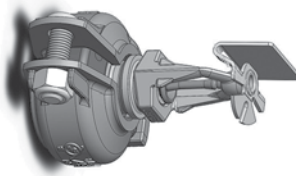

Horizontal Sidewall V2709
with Style V9 Sprinkler
Coupling

**STANDARD RESPONSE
COMMERCIAL – STANDARD ORIFICE**

**Horizontal Sidewall and
Recessed Horizontal Sidewall**
½" IGS Groove™ (15 mm)
½" (13 mm) Orifice
K5.6 (8.1 SI)


Refer to publication 40.11.



Temp. Rating		IGS™ Groove with Style V9 Coupling	
		Victaulic Part Number	Price Each
°F	°C	Horizontal Sidewall	
PLAIN BRASS FINISH			
155	68	S27JCCS410	\$48.00
200	93	S27JCFs410	48.00
286	141	S27JCJS410	48.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Model V2710

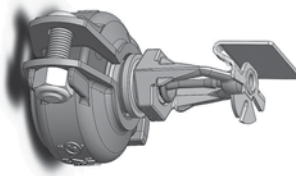

Horizontal Sidewall V2710
with Style V9 Sprinkler
Coupling

**QUICK RESPONSE
COMMERCIAL – STANDARD ORIFICE**

**Horizontal Sidewall and
Recessed Horizontal Sidewall**
½" IGS Groove™ (15 mm)
½" (13 mm) Orifice
K5.6 (8.1 SI)

Refer to publication 40.11.



Temp. Rating		IGS™ Groove with Style V9 Coupling	
		Victaulic Part Number	Price Each
°F	°C	Horizontal Sidewall	
PLAIN BRASS FINISH			
155	68	S27JCCQ410	\$74.00
200	93	S27JCFQ410	74.00
286	141	S27JCJQ410	74.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Sprinklers

FireLock™ Installation-Ready™ Models V3401 and V3405

**STANDARD RESPONSE
COMMERCIAL – LARGE ORIFICE**

**Upright, Pendent and Recessed Pendent
3/4" IGS™ Groove (20 mm)
17/32" (14 mm) Orifice
K8.0 (11.5 SI)**

Refer to publication 40.15.



Upright V3401
with Style V9
Sprinkler Coupling



Pendent V3405
with Style V9
Sprinkler Coupling



Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S34KAC510	S34KBCS510	\$56.00	\$56.00
200	93	S34KAF510	S34KBF510	56.00	56.00
286	141	S34KAJ510	S34KBJ510	56.00	56.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Models V3402 and V3406

**QUICK RESPONSE
COMMERCIAL – LARGE ORIFICE**

**Upright, Pendent and Recessed Pendent
3/4" IGS™ Groove (20 mm)
17/32" (14 mm) Orifice
K8.0 (11.5 SI)**

Refer to publication 40.15.



Upright V3402
with Style V9
Sprinkler Coupling



Pendent V3406
with Style V9
Sprinkler Coupling




Temp. Rating		IGS™ Groove with Style V9 Coupling			
		Victaulic Part Number		Price Each	
°F	°C	Upright	Pendent	Upright	Pendent
PLAIN BRASS FINISH					
155	68	S34KACQ510	S34KBCQ510	\$67.00	\$67.00
200	93	S34KAFQ510	S34KBQ510	67.00	56.00
286	141	S34KAJQ510	S34KBQ510	67.00	56.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Sprinklers

FireLock™ Installation-Ready™ Model V3409

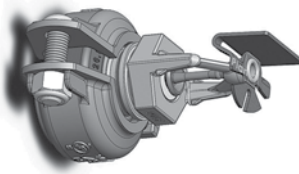

Horizontal Sidewall V3409
with Style V9 Coupling

**STANDARD RESPONSE
COMMERCIAL – LARGE ORIFICE**

**Horizontal Sidewall and
Recessed Horizontal Sidewall**
¾" IGS™ Groove (20 mm)
17/32" (14 mm) Orifice
K8.0 (11.5 SI)


Refer to publication 40.16.



Temp. Rating		IGS™ Groove with Style V9 Coupling	
		Victaulic Part Number	Price Each
°F	°C	Horizontal Sidewall	
PLAIN BRASS FINISH			
155	68	S34KCCS510	\$111.00
200	93	S34KCF510	111.00
286	141	S34KCJS510	111.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Model V3410

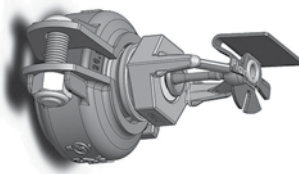

Horizontal Sidewall V3410
with Style V9 Coupling

**QUICK RESPONSE
COMMERCIAL – LARGE ORIFICE**

**Horizontal Sidewall and
Recessed Horizontal Sidewall**
¾" IGS™ Groove (20 mm)
17/32" (14 mm) Orifice
K8.0 (11.5 SI)

Refer to publication 40.16.



Temp. Rating		IGS™ Groove with Style V9 Coupling	
		Victaulic Part Number	Price Each
°F	°C	Horizontal Sidewall	
PLAIN BRASS FINISH			
155	68	S34KCCQ510	\$126.00
200	93	S34KCFQ510	126.00
286	141	S34KCJQ510	126.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Installation-Ready™ Sprinklers

FireLock™ Model V4998

EARLY SUPPRESSION FAST RESPONSE

Pendent
1" NPT (25 mm) Thread / IGS™ Groove
1" (25 mm) Orifice
K25.2 (36.8 SI)

Refer to publication 40.94.



Pendent
V4998

Temp. Rating		NPT Threaded Connection		IGS™ Groove with Style V9 Coupling		IGS™ Groove without Style V9 Coupling	
		Victaulic Part Number	Price Each	Victaulic Part Number	Price Each	Victaulic Part Number	Price Each
°F	°C	Pendent					
Plain Brass Finish							
165	74	S493SDR910	\$47.50	S49LSDR910	\$56.50	S49HSDR910	\$47.50
212	100	S493SGR910	47.50	S49LSGR910	56.50	S49HSGR910	47.50

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

FireLock™ Model V4996

EARLY SUPPRESSION FAST RESPONSE

Pendent
1" NPT (25 mm) Thread
1" (25 mm) Orifice
K22.4 (32.0 SI)

Refer to publication 40.95.



Pendent
V4996

Temp. Rating		NPT Threaded Connection	
		Victaulic Part Number	Price Each
°F	°C	Pendent	
Plain Brass Finish			
165	74	S493SDRM10	\$48.00
212	100	S493SGRM10	48.00

NOTE: Items listed in shaded areas are non-cancellable and non-returnable.

TERMS AND CONDITIONS OF SALE

Victaulic published Terms and Conditions of Sale listed in General Price List will apply. Prices, Designs and Conditions of Sale are subject to change without notice.

P.O. Box 31, Easton, PA 18044-0031 • 4901 Kesslersville Road, Easton, PA 18040 • 1-800-PICK-VIC (1-800-742-5842) • 1-610-250-8817 (fax) • pickvic@victaulic.com
